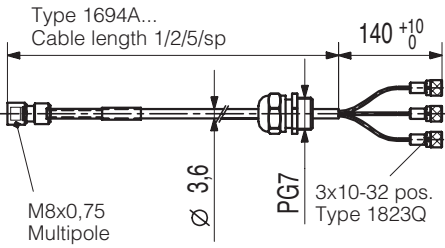

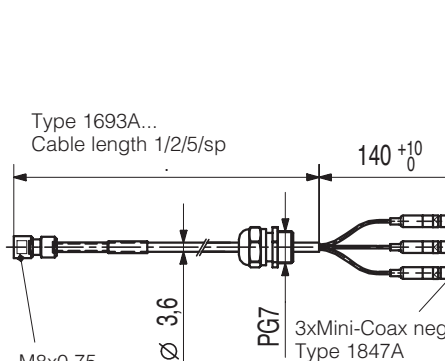
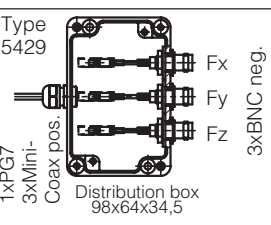
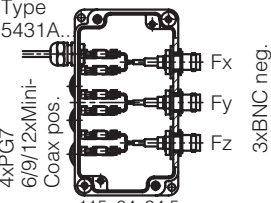
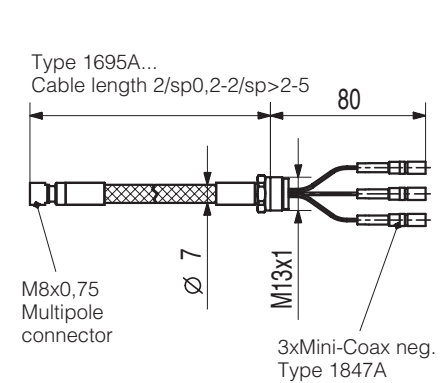
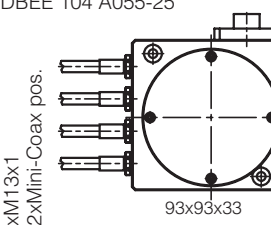


Mehrkomponenten Kraftmessanlagen mit Typen 9017A, 9047B, 9067B, 9077B  
 Systèmes pour mesurer à plusieurs composantes avec types 9017A, 9047B, 9067B, 9077B  
 Systems for Multicomponent Measurements with Types 9017A, 9047B, 9067B, 9077B

3-Component sensor	Set of preloading elements	3-Component force link
<p>Type 9017A 9018A 9016A4</p>	<p>Lieferumfang Scope of Delivery Etendue de la fourniture</p>	
<p>Type 9047B 9048B 9046B4</p>	<p>Type 9465 9465sp</p>	<p>Type 9347B 9348B</p>
<p>Type 9067B 9068B 9066B4</p>	<p>Type 9451A 9451Asp</p> <p>Type 9459</p>	<p>Type 9367B 9368B</p>
<p>Type 9077B 9078B 9076B4</p>	<p>Type 9455</p>	<p>Type 9377B 9378B</p>

000-183m-04.00 (IN06.9017/147/167/177m-04.00)

Protecting class	Connecting cable	Number of sensors	Summing box	Connecting cable	Charge amplifier	Output
IP65	 <p>Type 1694A... Cable length 1/2/5/sp 140 <sup>+10</sup>/<sub>0</sub> M8x0,75 Multipole connector Ø 3,6 PG7 3x10-32 pos. Type 1823Q</p>	1		 <p>Type 1721 10-32 neg.-BNC pos.</p>	<p>Type 3x 5011 5019Bx3x</p>	
	 <p>Type 1693A... Cable length 1/2/5/sp 140 <sup>+10</sup>/<sub>0</sub> M8x0,75 Multipole connector Ø 3,6 PG7 3xMini-Coax neg. Type 1847A</p>	1 ... 3	 <p>Type 5429 1xPG7 3xMini-Coax pos. Distribution box 98x64x34,5 3xBNC neg.</p>	<p>3x Type 1601C... BNC pos - BNC pos.</p>	<p>Type 5038A3 Type 5034A3</p>	<p>Fx Fy Fz</p>
		2	Type 5431A2			
		3	Type 5431A3			
		4	Type 5431A4			
			 <p>Type 5431A... 4xPG7 6/9/12xMini-Coax pos. 115x64x34,5 3xBNC neg.</p>			
IP67	 <p>Type 1695A... Cable length 2/sp0,2-2/sp&gt;2-5 80 M8x0,75 Multipole connector Ø 7 M13x1 3xMini-Coax neg. Type 1847A Cable welded to sensor</p>	1 ... 3	<p>Type 5433</p>	<p>Type 1687B5 1689B5</p>	<p>Type 5038A3 5034A3</p>	
		1 ... 4	<p>Fischer 9pole DBEE 104 A055-25</p>  <p>4xM13x1 12xMini-Coax pos. 93x93x33</p>	<p>Type 1677A5 1679A5</p>	<p>Type 5019Bx3x</p>	<p>Fx, Mx Fy, My Fz, Mz</p>